


# MV ARMORED TERMINATIONS

**Prysmian**  
MV ACCESSORIES

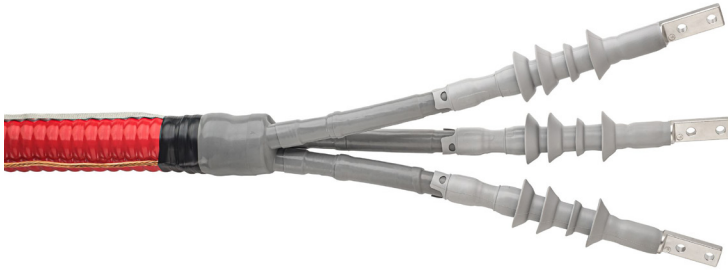

## DESCRIPTION

Prysmian has developed a quick and easy termination for ARMORED cable.

Two-hole lugs can be provided so that a complete kit is ready for the jobsite.

Add "-O" to below product number for outdoor or "-I" for indoor termination kits. If not specified, outdoor rated terminations will be assumed as requested.

Break Out Kits contain all the components needed to prepare the 3/C Cable to install a termination (no termination included).

### 1/C 5kV Terminations (Indoor or Outdoor)

Termination Kit	Cable Range	Insulation OD
AT1C5HS	#2 AWG - #1AWG	0.35" - 0.60"
AT1CA5-X	1/0 AWG - 3/0 AWG	0.57" - 0.98"
AT1CB5-X	4/0 AWG - 250 kcmil	0.67" - 1.10"
AT1CC5-X	350 kcmil - 500 kcmil	0.85" - 1.50"
AT1CD5-X	750 kcmil - 1000 kcmil	1.08" - 1.97"
AT1CE5-X	Larger Size	1.41" - 2.56"

### 3/C 5kV Terminations (Indoor or Outdoor)

Termination Kit	Break Out Kit	Cable Range	Insulation OD
AT3C5HS	ATB03C5HS	#2 AWG - #1AWG	0.35" - 0.60"
AT3CA5-X	ATB03C5A	1/0 AWG - 3/0 AWG	0.57" - 0.98"
AT3CB5-X	ATB03C5B	4/0 AWG - 250 kcmil	0.67" - 1.10"
AT3CC5-X	ATB03C5C	350 kcmil - 500 kcmil	0.85" - 1.50"
AT3CD5-X	ATB03C5D	750 kcmil - 1000 kcmil	1.08" - 1.97"
AT3CE5-X	ATB03C5E	Larger Size	1.41" - 2.56"

### 1/C 15kV Terminations (Indoor or Outdoor)

Termination Kit	Cable Range	Insulation OD
AT1CA15-X	#2 AWG - 3/0 AWG	0.57" - 0.98"
AT1CB15-X	#1 AWG - 250 kcmil	0.67" - 1.10"
AT1CC15-X	2/0 AWG - 500 kcmil	0.85" - 1.50"
AT1CD15-X	350 kcmil - 750 kcmil	1.08" - 1.97"
AT1CE15-X	1000 kcmil - 1500 kcmil	1.41" - 2.56"

### 3/C 15kV Terminations (Indoor or Outdoor)

Termination Kit	Break Out Kit	Cable Range	Insulation OD
AT3CA15-X	ATB03C15A	#2 AWG - 3/0 AWG	0.57" - 0.98"
AT3CB15-X	ATB03C15B	#1 AWG - 250 kcmil	0.67" - 1.10"
AT3CC15-X	ATB03C15C	2/0 AWG - 500 kcmil	0.85" - 1.50"
AT3CD15-X	ATB03C15D	350 kcmil - 750 kcmil	1.08" - 1.97"
AT3CE15-X	ATB03C15E	1000 kcmil - 1500 kcmil	1.41" - 2.56"

### 1/C 25kV Terminations (Outdoor Only)

Termination Kit	Cable Range	Insulation OD
AT1CB25-O	#2 AWG - 2/0 AWG	0.67" - 1.10"
AT1CC25-O	3/0 AWG - 250 kcmil	0.85" - 1.50"
AT1CD25-O	350 kcmil - 750 kcmil	1.08" - 1.97"
AT1CE25-O	500 kcmil - 1500 kcmil	1.41" - 2.56"

### 3/C 25kV Terminations (Outdoor Only)

Termination Kit	Break Out Kit	Cable Range	Insulation OD
AT3CB25-O	ATB03C25B	#2 AWG - 2/0 AWG	0.67" - 1.10"
AT3CC25-O	ATB03C25C	3/0 AWG - 250 kcmil	0.85" - 1.50"
AT3CD25-O	ATB03C25D	350 kcmil - 750 kcmil	1.08" - 1.97"
AT3CE25-O	ATB03C25E	500 kcmil - 1500 kcmil	1.41" - 2.56"

### 1/C 35kV Terminations (Outdoor Only)

Termination Kit	Cable Range	Insulation OD
AT1CC35-O	1/0 AWG - 4/0 AWG	0.67" - 1.10"
AT1CD35-O	250 kcmil - 350 kcmil	0.85" - 1.50"
AT1CE35-O	500 kcmil - 750 kcmil	1.08" - 1.97"
AT1CF35-O	750 kcmil - 1000 kcmil	1.41" - 2.56"

### 3/C 35kV Terminations (Outdoor Only)

Termination Kit	Break Out Kit	Cable Range	Insulation OD
AT3CC35-O	ATB03C35C	1/0 AWG - 4/0 AWG	0.67" - 1.10"
AT3CD35-O	ATB03C35D	250 kcmil - 350 kcmil	0.85" - 1.50"
AT3CE35-O	ATB03C35E	500 kcmil - 750 kcmil	1.08" - 1.97"
AT3CF35-O	ATB03C35F	750 kcmil - 1000 kcmil	1.41" - 2.56"