


# PVC Insulated Ground Wire

BELL SYSTEM TYPE

# Spec. 2621

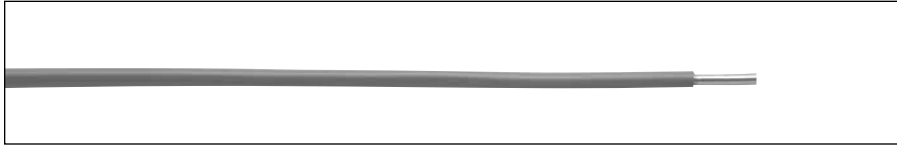

**Product Construction:**

**Conductor:**

- Solid annealed copper

**Insulation:**

- Light olive gray, flame-retardant, weather- and abrasion-resistant PVC compound extruded over the conductor

**Application(s):**

- Single conductor for connection to ground for customer premises or network equipment and station protectors

**Compliances:**

- Telcordia (Bellcore) Specification TA-TSY-000120
- UL Listed VW-1
- RoHS Compliant (effective 1/1/10)

**Packaging:**

- Available in coils (CL) and coils in cartons (CL/CTN)

**Nominal Cable Data**

CATALOG NUMBER	AWG	CABLE CODE	NOM. O.D. (INCHES)	WEIGHT (LBS/MFT)	STANDARD LENGTH (FT)
7515307	6	V-61-C	0.22	102	600 CL
7515265	10	V-101-C	0.15	39	200 CL/CTN

Data subject to change without notice. Contact your Customer Service Representative for latest information.



Passes UL VW-1 Flame Test

Underwriters Laboratories Inc.



# Bare Ground Wire

BELL SYSTEM TYPE

# Spec. 2622



**Product Construction:**

**Conductor:**

- Solid annealed copper

**Application(s):**

- Single conductor for grounding aerial cables and pole-mounted equipment. Proper telephone co. grounding practices must be followed

**Compliances:**

- Telcordia (Bellcore) Specification TA-TSY-000120
- ASTM B-3
- RoHS Compliant (effective 1/1/10)

**Packaging:**

- Available in coils (CL) and coils in cartons (CL/CTN)

**Nominal Cable Data**

CATALOG NUMBER	AWG	CABLE CODE	NOM. O.D. (INCHES)	WEIGHT (LBS/MFT)	STANDARD LENGTH (FT)
2091090	6	B-6	0.16	86	50 CL/CTN
2091093	6	B-6	0.16	86	600 CL

Data subject to change without notice. Contact your Customer Service Representative for latest information.

